


Shock SLZ-16--KF-A

Part number: 114031

FESTO

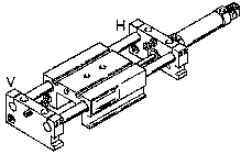

Datasheet

Feature	Value
Function	shock absorber
Cushioning	self-adjustable
Type of mounting	Thread + lock nut
Thread type	M
Thread diameter (metric)	10 mm
Pitch	0,75 mm
Thread length	30 mm
Piston, nominal size	8
Stroke	8
Cushioning work per stroke	4 J
Cushioning work per hour	24000 J
Impact speed max.	3 m/s
Impact force max.	400 N
Reset force	15 N
Residual energy max.	0,01 J
Piston rod diameter	4 mm
Diameter	8 mm
Distance	16 mm
Width	4 mm
Length	77 mm
Overall length	93 mm
Minimum ambient temperature	-10 °C
Maximum ambient temperature	80 °C
Reset time, short term	0,4 s
Reset time, long term	1 s
Permissible tightening torque	5 Nm
Material of seals	NBR-Elastomer
Material of piston rod	Steel with special properties
Material of barrel/housing	Steel
Silicone status	Free
Product weight	0,04 kg
Width across flats	13 mm