


Clamping module EV-12-3

Part number: 150681

FESTO

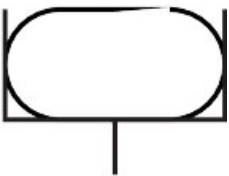

Data sheet

Feature	Value
Stroke	3 mm
Clamping surface	Diameter 12
Mounting position	optional
Mode of operation	Single-acting
Operating pressure	0.6 MPa 6 bar 87 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...40 °C
Product weight	11 g
Type of mounting	With through-hole
Pneumatic connection	M3
Material housing	Die-cast aluminium
Material membrane	TPE-U(PU)