


One-way GRLA-M5-PK-3-LF-B

Part number: 161413

FESTO

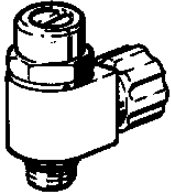

Datasheet

Feature	Value
Function	One-way flow control
Function air supply/exhaust air	Exhaust air
Function restrictor	Adjustable
Actuating component	Screw
Type of mounting	Screw-in
Nominal size flow control	2 mm
Nominal size non-return	2 mm
Air connection type 1	Male thread
Air connection type 1	Barbed fitting
Thread for port 1	M 5
Nominal size tubing connection 2	3
Operating pressure min.	0,2 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-10 °C
Maximum ambient temperature	60 °C
Minimum medium temperature	-10 °C
Maximum medium temperature	60 °C
Standard nom. flow rate 1->2(S) max.	40 l/min
Standard nom. flow rate 1->2(S) min	0 l/min
Standard nominal flow rate 2->1 max.	88 l/min
Standard nominal flow rate 2->1 min	77 l/min
Medium	Compressed air, filtered 40 µm (may be lubricated)