 



# Fine filter LFMB-1/2-H-A

Part number: 162818

FESTO

With 1 µm filter cartridge, metal bowl guard.  
Discontinued, available through 2008

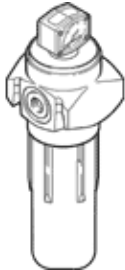

## Data sheet

Feature	Value
Assembly position	Vertical +/- 5°
Grade of filtration	1 µm
Filter efficiency	99.9999 %
Condensate drain	fully automatic
Design structure	Fibre filter
Differential pressure display	Pressure gauge
Inlet pressure 1	0 ... 16 bar
Standard nominal flow rate	1,600 l/min
Operating medium	Filtered compressed air, 5 µm filtration
Storage temperature	-10 ... 60 °C
Medium temperature	1.5 ... 60 °C
Residual oil content	0.5 mg/m <sup>3</sup>
Ambient temperature	-10 ... 60 °C
Mounting type	Optional Line installation with accessories
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/2
Materials information for filter	Boron silicate fibre
Materials information, housing	Zinc die-casting
Materials information for bowl	Zinc die-casting