

 

Linear drive DGPL-11/16"- -PPV-A-KF-B

Part number: 162940

FESTO

For proximity sensing, rodless, with positive-locking connection between piston and driver and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

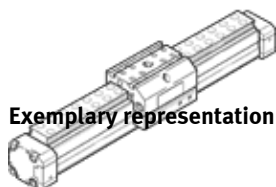

Exemplary representation

Data sheet

Feature	Value
Stroke	10 ... 3,000 mm
Piston diameter	11/16"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends YXR: Shock absorber, hard characteristic curve
Guide	Recirculating ball bearing guide
Driver principle	positive-locking (slot)
Operating pressure	2 ... 8 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Ambient temperature	-10 ... 60 °C
Cushioning length	16 mm
Pneumatic connection	UNF10-32