


 
Linear drive DGPL-3"- -PPV-A-KF-B

Part number: 162946

FESTO

For proximity sensing, rodless, with positive-locking connection between piston and driver and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

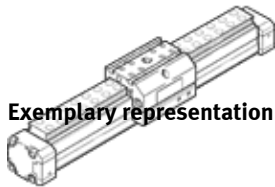

Exemplary representation

Data sheet

| Feature | Value |
|----------------------|---|
| Stroke | 10 ... 3,000 mm |
| Piston diameter | 3" |
| Cushioning | PPV: Pneumatic cushioning adjustable at both ends YXR: Shock absorber, hard characteristic curve |
| Guide | Recirculating ball bearing guide |
| Driver principle | positive-locking (slot) |
| Operating pressure | 1.5 ... 8 bar |
| Mode of operation | double-acting |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Ambient temperature | -10 ... 60 °C |
| Cushioning length | 83 mm |
| Pneumatic connection | NPT1/2-14 |