


# One-way GRLA-1/8-QS-4-RS-B

Part number: 162964

FESTO

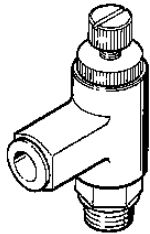

## Datasheet

Feature	Value
Function	One-way flow control
Function air supply/exhaust air	Exhaust air
Function restrictor	Adjustable
Actuating component	Rotary knob
Type of mounting	Screw-in
Nominal size flow control	3 mm
Nominal size non-return	3 mm
Air connection type 1	Male thread
Air connection type 1	Push-in
Thread for port 1	G 1/8
Nominal size tubing connection 2	4
Operating pressure min.	0,3 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-10 °C
Maximum ambient temperature	60 °C
Minimum medium temperature	-10 °C
Maximum medium temperature	60 °C
Material of seals	NBR, TPE-U(PU)
Product weight	0,026 kg
Standard nom. flow rate 1->2(S) max.	150 l/min
Standard nom. flow rate 1->2(S) min	0 l/min
Standard nominal flow rate 2->1 max.	230 l/min
Standard nominal flow rate 2->1 min	165 l/min
Medium	Compressed air, filtered 40 µm (may be lubricated)