

# stopper cylinder STAF-32-20-P-A-K


Part number: 164880  
Product to be discontinued

FESTO

With toggle lever and built-in flange plate.

This product may not be used within liquid media. Easy retrofitting to a double-acting cylinder is possible.

Type to be discontinued. Available until 2022. See Support Portal for alternative products.

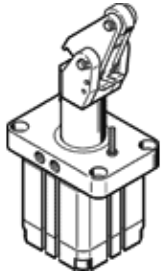

## Data sheet

Feature	Value
Stroke	20 mm
Piston diameter	32 mm
Cushioning	P: Flexible cushioning rings/plates at both ends
Assembly position	Vertical
Mode of operation	single-acting pulling action
Design structure	Piston rod with toggle lever
Position detection	For proximity sensor
Variants	Single-ended piston rod
Protection against torque/guide	Guide rod
Operating pressure	1.5 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	0 ... 60 °C
Permissible impact force on the advanced piston rod	480 N
Product weight	750 g
Mounting type	with through hole
Pneumatic connection	M5
Materials note	Free of copper and PTFE
Material cover	Aluminium
Material seals	NBR
Material housing	Aluminium
Material piston rod	High alloy steel, non-corrosive
Material roll	POM