


Intermediate ILR-03-ZP-B-7,0

Part number: 164946

FESTO

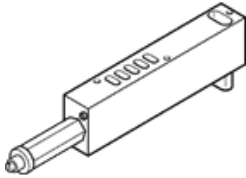

Datasheet

| Feature | Value |
|-----------------------------------|---------------------------------|
| Image code | F10 |
| Design regulating valve | piston |
| Type of pilot control | Direct |
| Behaviour during flow reversal | Non-return valve |
| Control direction | I->II |
| Modular design | Yes |
| Supply pressure I min. | 0 bar |
| Supply pressure I max. | 10 bar |
| Output pressure II min. | 0 bar |
| Output pressure II max. | 8 bar |
| Connection type I | Sub-base |
| Connection type II | Sub-base |
| Installation position | certain |
| Type of mounting | Screw-in |
| Length | 218,5 mm |
| Length | 187 mm |
| Total height | 36,1 mm |
| Total width | 24,5 mm |
| Minimum ambient temperature | -10 °C |
| Maximum ambient temperature | 60 °C |
| Minimum temperature of medium | -10 °C |
| Maximum temperature of medium | 60 °C |
| Pressure gauge yes/no | No |
| Number pressure gauge connections | 1 |
| Thread type pressure gauge thread | M |
| Thread diameter (metric) | 5 mm |
| Distance | 26,5 mm |
| Material of seals | NBR-Elastomer |
| Silicone status | Free |
| Standard nominal flow rate I-II | 420 l/min |
| Medium of operation | Filtered compressed air (40 µm) |
| Leakage | 5 l/h |