


# Accessory CPE10-PRSE-1

Part number: 164961

FESTO

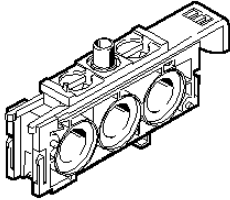

## Datasheet

Feature	Value
Total length	24,2 mm
Width	86,5 mm
Height	12,1 mm
Type of mounting sub-base	Screw
Linking options for sub-base	Yes
Operating pressure min.	-0,9 bar
Operating pressure max.	10 bar
Minimum ambient temperature	-5 Cel
Maximum ambient temperature	50 Cel
Minimum temperature of medium	-5 Cel
Maximum temperature of medium	50 Cel
Minimum storage temperature	-20 Cel
Maximum storage temperature	40 Cel
Ducted main ports	1+3+5
Connection type connection 1	Thread
Connection type connections 3,5	Thread
Connection side, port 1	On front face
Connection side, port 3	On front face
Connection side, port 5	On front face
Thread type connection 1	G
Thread diameter (inch)	1/4 inch
Thread type connections 3,5	G
Thread diameter (inch)	1/4 inch
Silicone status	Free
CT criterion	CT-free
Length	9,6 mm
Length	6,5 mm
Distance	60 mm
Medium of operation	Filtered compressed air