


elbow quick connector LCKN-3/8-PK-6

Part number: 165002

FESTO

360° orientable, with sealing ring.

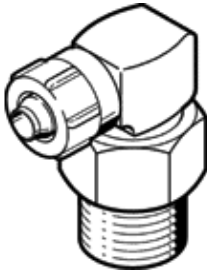

Data sheet

Feature	Value
Nominal size	4.6 mm
Type of seal on screw-in stud	Sealing ring
Assembly position	Any
Operating pressure complete temperature range	-0.9 ... 16 bar
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Ambient temperature	-20 ... 80 °C
Pneumatic connection, port 1	Male thread G3/8
Pneumatic connection, port 2	for barbed connector internal diameter 6 mm with nut
Materials information, housing	Zinc die-casting