

 

# Intermediate pressure regulator plate LR-ZP-B-D-3-CT

Part number: 165858

FESTO

For ISO valves.

Products to be discontinued. Available until 2010.

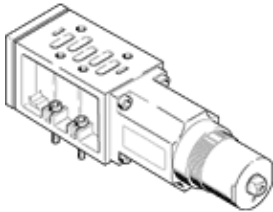

## Data sheet

Feature	Value
Based on the standard	ISO 5599-1
Integrated function	Pressure regulator
Design structure	Piston
Pressure control range	0 ... 12 bar
Inlet pressure 1	$\leq 14$ bar
Product weight	1,220 g
Materials note	Free of copper and PTFE Conforms to RoHS
Materials information for seals	NBR
Materials information, housing	Aluminium die cast Steel