


# plug socket MSSD-C-4P

Part number: 171157

FESTO

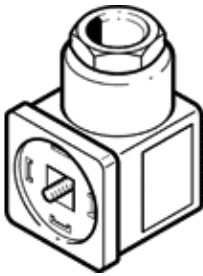

## Data sheet

Feature	Value
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	22 g
Electrical connection	3-pin Plug socket angled Plug pattern type A to EN 175301-803 Per DIN EN 175301-803 Rectangular design, MSC Rectangular design, MSN1
Cable gland connection	Pg9
Cable diameter	6 ... 8 mm
Nominal conductor cross-section	$\leq 1.5 \text{ mm}^2$
Protection class	IP65
Ambient temperature	-25 ... 90 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	Plastic
Housing colour	Black