

## filter

### LF-1/8-D-MINI-NPT

 

Part number: 173676

Classic - do not use for new projects

FESTO

With metal bowl guard.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

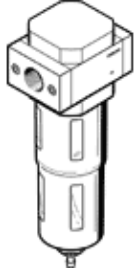

## Data sheet

Feature	Value
Size	Mini
Series	D
Assembly position	Vertical
Grade of filtration	40 µm
Condensate drain	manual momentary-contact
Max. condensate volume	22 cm <sup>3</sup>
Bowl guard	Metal bowl guard
Operating pressure	0 ... 16 bar
Standard nominal flow rate	1,000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [-:9:-] Inert gases
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-10 ... 60 °C
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:8:4] Inert gases
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting type	Line installation With mounting bracket Optional
Pneumatic connection, port 1	1/8 NPT
Pneumatic connection, port 2	1/8 NPT
Materials note	Conforms to RoHS
Material filter	PE
Material housing	Zinc die-casting
Material bowl	PC