

 

# lubricator LOE-1/2-D-MIDI-NPT

Part number: 173824  
Classic - do not use for new projects

FESTO

With metal bowl guard.

Modern alternatives can be found by entering the first four characters of the type code in the search field.

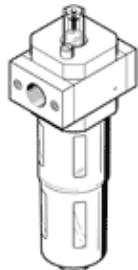

## Data sheet

Feature	Value
Max. oil capacity	110 cm <sup>3</sup>
Bowl guard	Metal bowl guard
Operating pressure	16 bar
Minimum flow rate for lubricator function	8 l/min
Standard nominal flow rate	6,100 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation not possible
PWIS conformity	VDMA24364-B1/B2-L
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:4:-] Inert gases
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Mounting type	with accessories
Pneumatic connection, port 1	1/2 NPT
Pneumatic connection, port 2	1/2 NPT
Materials note	Conforms to RoHS
Material bowl	PC