

branching module FRM-H-1-D-MAXI-NPT

 

Part number: 173939

Classic - do not use for new projects

[Pneumatic manifold with 4 connections.](#)

[Modern alternatives can be found by entering the first four characters of the type code in the search field.](#)

FESTO

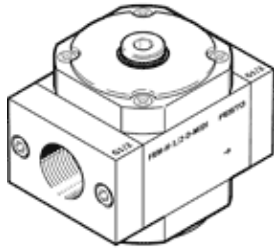

Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Operating pressure	0.25 ... 16 bar
Standard nominal flow rate in main flow direction 1->2	12,300 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-10 ... 60 °C
Air purity class at output	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	776 g
Pneumatic connection, port 1	1 NPT
Pneumatic connection, port 2	1 NPT
Pneumatic connection, port 3	G3/4
Pneumatic connection, port 4	G1/4
Materials note	Conforms to RoHS
Material housing	Zinc die-casting