


# Valve terminal CPA14-VI

Part number: 174001

FESTO

Valve terminal CPA, grid dimension 14 mm.  
Type to be discontinued. Available until 2013.

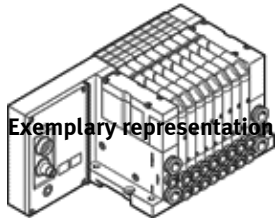

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Valve function	2x3/2 closed, monostable 2x3/2 open, monostable 2x3/2 open/closed, monostable 5/2 bistable 5/2 monostable 5/3 pressurised 5/3 exhausted 5/3 closed
Standard nominal flow rate	600 l/min
Operating pressure	-0.9 ... 10 bar
Electrical connection	AS-Interface Individual connection Fieldbus Multi-pin plug
Max. number of valve positions	22
Max. no. of pressure zones	11
Electrical I/O system	Yes
Ambient temperature	-5 ... 50 °C
Width	14 mm
Protection class	IP65
Authorisation	C-Tick
Grid dimension	14 mm
Type of actuation	electrical
Valve terminal type	12
Design structure	Piston slide
Pilot air supply	external Internal
Valve terminal structure	modular and expandable
Switching position indicator	LED
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
CE mark (see declaration of conformity)	to EU directive for EMC
Corrosion resistance classification CRC	2
Medium temperature	-5 ... 50 °C