


plug socket with cable KMEB-2-230-2,5

Part number: 174846

FESTO

Pre-assembled, for MEBH, MOEBH valves and N2 solenoids.

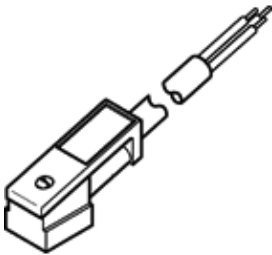

Data sheet

Feature	Value
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	200 g
Electrical connection	4-pin Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803
Nominal operating voltage, AC	230 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	6.2 mm
Cable structure	3x0,75
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material cable sheath	TPE-U(PUR)
Material housing	PA POM
Material electrical contact	Bronze