


Proximity SMT0-4-PS-K5-LED-24

Part number: 175402

FESTO

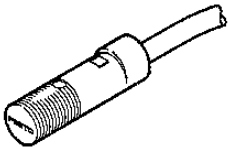

Datasheet

Feature	Value
EU conformity (CE)	CE
Note on EU conformity	Electromagnetic compatibility
Signal processing/type of contact	Inductive
Function on actuation	N/O contact
Output potential (el. output)	PNP
Switching accuracy (+/-)	0,1 mm
Air connection type elec.	Cable
Number of cores	3
Length of cable	5000 mm
Operating status display	Yellow LED
Type of mounting	Mounting kit
Installation position	Any
Response time ON	0,3 ms
Response time OFF	2,7 ms
Material of housing	Die-cast zinc
Material, cable sheath	TPE-U(PU)
Voltage type	DC
Nominal operating voltage [DC]	24 V
Operating voltage min. (DC)	10 V
Operating voltage max. (DC)	30 V
Maximum voltage drop	3 V
Switching current max.	200 mA
Idle current max.	8 mA
Contact rating max. (DC)	6 W
Degree of protection as per IEC 529 IP	..67