


# Connecting cable KMP1-02-VI-16-10

Part number: 175590  
Product to be discontinued

FESTO

For valve terminal VIMP-02, fully assembled for 12 to 16 valve positions,  
10 m long

Type to be discontinued. Available until 2017. See Support Portal for  
alternative products.

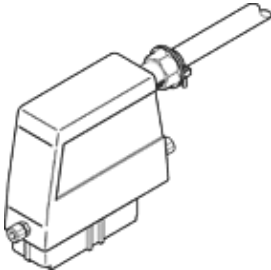

## Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	$\leq 300$ V
Operating voltage range DC	$\leq 250$ V
Permissible current load	4 A
Protection class	IP65
Ambient temperature with flexible cable installation	5 ... 70 °C
Ambient temperature	-30 ... 70 °C
Product weight	5,800 g
Electrical connection	40-pin Plug socket
Cable structure	39 x 0,75 mm <sup>2</sup>
Cable diameter	17 mm
Cable length	10 m
Mounting type	With clamp strap
Materials information, housing	Die-cast light alloy
Materials information, cable sheaths	PE
Material information for crimp connectors	Copper alloy Silver plated