 



# silencer UC-QS-8H

Part number: 175611

FESTO

For CPE valves or CPV valve terminals, with connector socket for QS fittings.

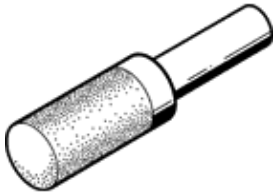

## Data sheet

| Feature                            | Value  |
|------------------------------------|--|
| Assembly position                  | Any  |
| Container size                     | 1  |
| Operating pressure MPa             | 0 ... 1 MPa  |
| Operating pressure                 | 0 ... 10 bar   |
| Flow rate to atmosphere            | 1,500 l/min  |
| Operating medium                   | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible                            |
| PWIS conformity                    | VDMA24364-B1/B2-L  |
| Sound pressure level               | 60 dB(A)   |
| Ambient temperature                | -10 ... 70 °C  |
| Product weight                     | 2.3 g  |
| Pneumatic connection               | QS-8   |
| Material of silencer insert        | PE   |
| Material of threaded plug          | PE   |
| Materials note                     | Conforms to RoHS   |