


# swivel flange SNCB-125-R3

Part number: 176950

FESTO

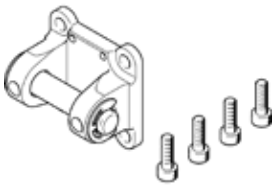

## Data sheet

| Feature                                 | Value   |
|---|---|
| Size                                    | 125   |
| Based on the standard                   | ISO 15552                                     |
| Variants                                | Excellent corrosion protection                |
| Corrosion resistance classification CRC | 3 - High corrosion stress                     |
| PWIS conformity                         | VDMA24364-B1/B2-L                             |
| RSBP classification to CD-0033          | F5a   |
| Ambient temperature                     | -40 ... 90 °C                                 |
| Product weight                          | 1,776 g                                       |
| Materials note                          | Conforms to RoHS                              |
| Material mounting                       | Aluminium die cast<br>With protective coating |
| Material mounting pin                   | High alloy steel, non-corrosive               |
| Material bearing                        | Plastic                                       |
| Material disc                           | steel, galvanized                             |
| Material screws                         | High alloy steel, non-corrosive               |
| Material lock                           | Spring steel, galvanised                      |