


Multi-pin plug socket IMP1-SD-40

Part number: 18318

FESTO

Products to be discontinued. Available until 2011.

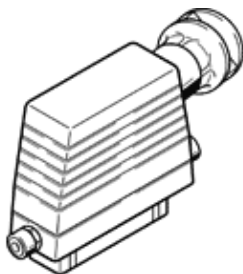

Data sheet

| Feature | Value |
|---|---------------------------------|
| Permissible cable diameter | 18 ... 27 mm |
| Assembly position | Any |
| Operating voltage range AC | ≤ 300 V |
| Operating voltage range DC | ≤ 250 V |
| Permissible current load | 10 A |
| Protection class | IP65 |
| Ambient temperature | -40 ... 125 °C |
| Product weight | 395 g |
| Terminal cross-section | 1.5 mm ² |
| Electrical connection | Plug socket 40-pin |
| Cable gland connection | Pg29 |
| Mounting type | With clamp strap |
| Materials information, housing | Plastic Die-cast light alloy |
| Material information for crimp connectors | Copper alloy Silver plated |