 



front panel valve SV/O-3-PK-3X2

Part number: 184135

FESTO

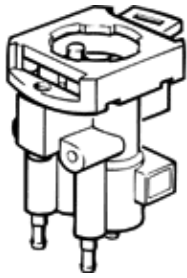

Data sheet

Feature	Value
Valve function	2x3/2 closed, monostable
Standard nominal flow rate	70 l/min
Operating pressure	0 ... 8 bar
Type of reset	mechanical spring
Nominal size	2.5 mm
Sealing principle	soft
Assembly position	Any
Type of piloting	direct
Flow direction	non reversible
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	34 g
Mounting type	with through hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Material seals	NBR