


t-adapter FB-TA-1

Part number: 18499

FESTO

For fieldbus connection to valve and valve/sensor terminals.

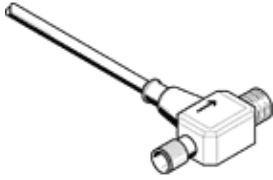

Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 10 V
Operating voltage range DC	≤ 30 V
Permissible current load	4 A
Protection class	IP67
Ambient temperature	-25 ... 90 °C
Product weight	23 g
Electrical connection	Plug / socket M12x1 / M12x1 5-pin / 5-pin
Cable structure	2x0,25
Cable diameter	5 mm
Mounting type	With sleeve nut
Materials information, housing	PA
Materials information, cable sheaths	PVC
Material information for crimp connectors	Brass Nickel and tin plated