


# DUO cable KM12-DUO-M8-WDWD

Part number: 18687

FESTO

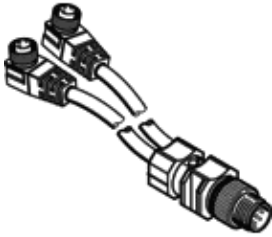

## Data sheet

Feature	Value
Operating voltage range AC	$\leq 60$ V
Operating voltage range DC	$\leq 75$ V
Permissible current load	2.8 A
Protection class	IP67
Ambient temperature with flexible cable installation	-5 ... 70 °C
Ambient temperature	-30 ... 70 °C
Electrical connection	Plug straight / socket angled M12x1 / M8x1 3-pin / 3-pin
Cable structure	3x0,25
Cable length	0.6 m
Cable sheath colour	Grey
Materials information, cable sheaths	PUR