


cable socket ASI-SD-FK-M12

Part number: 18788

FESTO

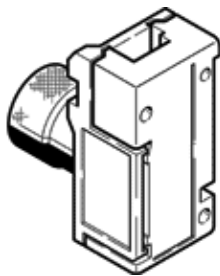

Data sheet

Feature	Value
Assembly position	Any
Operating voltage range AC	≤ 40 V
Permissible current load	2 A
Protection class	IP65 IP67
Ambient temperature	-25 ... 60 °C
Product weight	16.8 g
Terminal cross-section	1.5 mm ²
Electrical connection	5-pin Straight socket / insulation displacement technology
Mounting type	With sleeve nut
Housing colour	Black
Materials information for locknut	Nickel plated
Materials information, housing	PA
Material information for crimp connectors	Copper alloy Gold plated