


# cable socket ASI-SD-PG-M12

Part number: 18789

FESTO

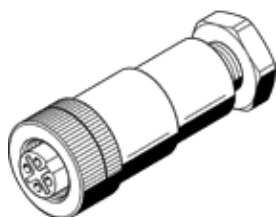

## Data sheet

Feature	Value
Mounting type	With sleeve nut
Assembly position	Any
Product weight	27.6 g
Electrical connection	4-pin Plug socket, straight Screwed terminal
Operating voltage range AC	$\leq 125$ V
Permissible current load	3 A
Cable gland connection	Pg9
Terminal cross-section	0.75 mm <sup>2</sup>
Protection class	IP65 IP67
Ambient temperature	-40 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA
Housing colour	Black
Material of union nut	Nickel plated
Material electrical contact	Bronze