


# suction gripper ESG-4

Part number: 189168

FESTO

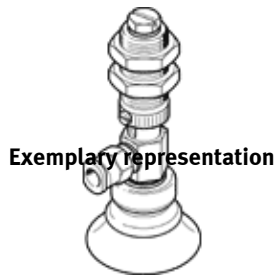

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
suction cup diameter	4 mm
Assembly position	Vertical
Special characteristics	Antistatic
Design structure	Vacuum connection at top Vacuum connection at side with height compensation With long height compensator
Correlation to suction-cup holder	Size 1
Suction cup shape	round flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-30 ... 200 °C
Vacuum connection	M3 M10x1 QS-4 PK-3
Materials note	Conforms to RoHS
Material suction cup	BR FPM NBR PUR VMQ (silicon)