


suction gripper ESG-8

Part number: 189170

FESTO

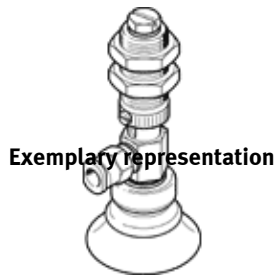

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
suction cup diameter	8 mm
Assembly position	Vertical
Special characteristics	Antistatic
Design structure	Vacuum connection at top Vacuum connection at side with height compensation With long height compensator
Correlation to suction-cup holder	Size 2
Suction cup shape	round flat
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-30 ... 200 °C
Vacuum connection	M5 M10x1 QS-6 PK-4
Materials note	Conforms to RoHS
Material suction cup	BR FPM NBR PUR VMQ (silicon)