


suction gripper ESG-30

Part number: 189174

FESTO

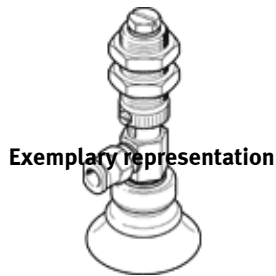

Exemplary representation

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
suction cup diameter	30 mm
Assembly position	Vertical
Special characteristics	Antistatic
Design structure	Vacuum connection at top Vacuum connection at side with height compensation With long height compensator
Correlation to suction-cup holder	Size 4
Suction cup shape	round flat Round deep Round, extra deep Round, bellows 1.5 conv Round, bellows, 3.5 convolutions
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-30 ... 200 °C
Vacuum connection	M14x1 G1/8 QS-6 PK-4
Materials note	Conforms to RoHS
Material suction cup	BR FPM NBR PUR VMQ (silicon) Vulkollan®