


suction gripper ESG-100

Part number: 189179

FESTO

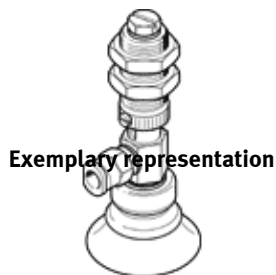

Data sheet

Overall data sheet – Individual values depend upon your configuration.

| Feature | Value |
|---|---|
| suction cup diameter | 100 mm |
| Assembly position | Vertical |
| Design structure | Vacuum connection at top Vacuum connection at side with height compensation With long height compensator |
| Correlation to suction-cup holder | Size 5 |
| Suction cup shape | round flat Round deep Round, extra deep |
| Operating medium | Atmospheric air based on ISO 8573-1:2010 [7::-] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | -30 ... 200 °C |
| Vacuum connection | G1/8 G1/4 |
| Materials note | Conforms to RoHS |
| Material suction cup | FPM NBR PUR VMQ (silicon) Vulkollan® |