


# suction cup holder ESH-HA-6-G

Part number: 189202

FESTO

without height compensator, vacuum connection at top, compensator secured by two hexagonal nuts.

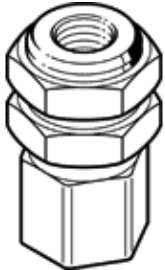

## Data sheet

Feature	Value
Volume	7.234 cm <sup>3</sup>
Assembly position	Vertical
Design structure	Vacuum connection at top
Correlation to suction-cup holder	Size 6
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:~]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 60 °C
Product weight	200 g
Mounting type	with lock nut
suction cup mounting	M20x2
Vacuum connection	G1/4
Materials note	Conforms to RoHS
Material bracket	Aluminium Nickel-plated brass POM Heat-treatment steel High alloy steel