


# suction cup holder ESH-HB-2-QS

Part number: 189205

FESTO

without height compensator, vacuum connection at side.

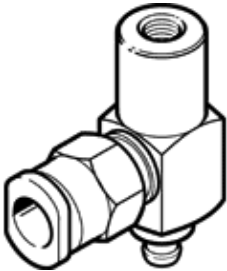

## Data sheet

Feature	Value
Volume	0.418 cm <sup>3</sup>
Assembly position	Vertical
Design structure	Vacuum connection at side
Correlation to suction-cup holder	Size 2
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:--]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	0 ... 60 °C
Product weight	13 g
Mounting type	with internal (female) thread
suction cup mounting	Diameter 4 mm
Vacuum connection	QS-6
Materials note	Conforms to RoHS
Material seals	NBR Steel
Material bracket	Aluminium Nickel-plated brass POM Heat-treatment steel High alloy steel