


suction cup holder ESH-HD-3-PK

Part number: 189238

FESTO

with height compensator, vacuum connection at side, compensator secured by two hexagonal nuts.

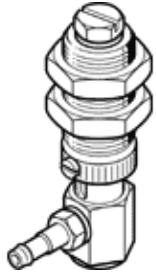

Data sheet

Feature	Value
Height compensator for suction-cup holder	6 mm
Volume	0.343 cm ³
Assembly position	Vertical
Design structure	Vacuum connection at side with height compensation
Correlation to suction-cup holder	Size 3
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 60 °C
Product weight	44 g
Mounting type	with lock nut
suction cup mounting	M4
Vacuum connection	PK-4
Materials note	Conforms to RoHS
Material seals	NBR Steel
Material bracket	Aluminium Nickel-plated brass POM Heat-treatment steel High alloy steel