


suction cup holder

ESH-HE-3-G1/8

Part number: 189255

FESTO

without height compensator, for direct screw-in fitting.

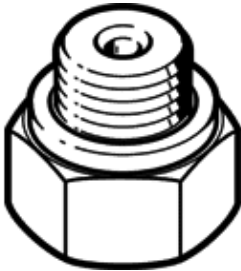

Data sheet

Feature	Value
Nominal size	3 mm
Volume	0.106 cm ³
Assembly position	Vertical
Design structure	Vacuum connection at top
Correlation to suction-cup holder	Size 3
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 60 °C
Product weight	11 g
Mounting type	with external (male) thread Via vacuum port
suction cup mounting	M4
Vacuum connection	G1/8
Materials note	Conforms to RoHS
Material seals	Wrought Aluminium alloy NBR POM Steel
Material bracket	Heat-treatment steel