


# suction cup holder

## ESH-HF-4-M14X1

Part number: 189263

FESTO

with height compensator, for direct screw-in fitting.

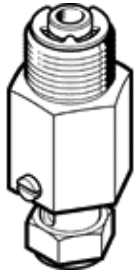

### Data sheet

Feature	Value
Height compensator for suction-cup holder	6 mm
Nominal size	4 mm
Volume	0.655 cm <sup>3</sup>
Assembly position	Vertical
Design structure	Vacuum connection at top with height compensation
Correlation to suction-cup holder	Size 4
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-A1-L
Ambient temperature	-10 ... 60 °C
Product weight	52 g
Mounting type	with external (male) thread Via vacuum port
suction cup mounting	M6
Vacuum connection	M14x1
Materials note	Conforms to RoHS
Material seals	NBR POM
Material bracket	Heat-treatment steel