


**push-in T-connector**  
**QST-5/8T-U**  
 Part number: 190606

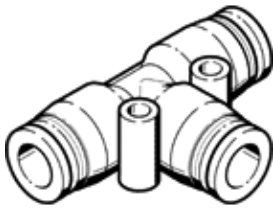

**Data sheet**

<b>Feature</b>	<b>Value</b>
Size	Standard
Nominal size	10.7 mm
Assembly position	Any
Container size	1
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 60 °C
Product weight	43.5 g
Number of outputs	2
Number of supply lines	1
Pneumatic connection, port 1	For hose external diameter 5/8"
Pneumatic connection, port 2	For hose external diameter 5/8"
Colour of release ring	Grey
Materials note	Conforms to RoHS
Material housing	PBT
Material release ring	POM
Material of tubing seal	NBR
Material of tube retaining claw	High alloy steel, non-corrosive