

Push-in T-fitting QSMT-10-32-UNF-5/32-U


Part number: 190813

FESTO

rotatable by 360°, male thread with external hexagon.

This product is only available if ordered from the Festo Corporation, USA.

Type to be discontinued. Available until 2013. See Support Portal for alternative products.

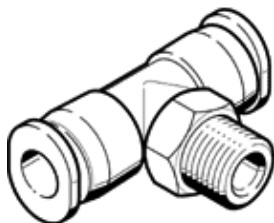

Data sheet

Feature	Value
Size	Mini
Nominal size	2.2 mm
Type of seal on screw-in stud	Sealing ring
Assembly position	Any
Container size	1
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1
Ambient temperature	-10 ... 60 °C
Authorisation	Germanischer Lloyd
Max. tightening torque	1.5 Nm
Product weight	4.5 g
Number of outputs	2
Number of supply lines	1
Pneumatic connection, port 1	Male thread UNF10-32
Pneumatic connection, port 2	for tubing, 5/32" outside diameter
Colour of release ring	Grey
Materials note	Conforms to RoHS
Materials information, housing	PBT
Release ring material data	POM
Materials information for tubing seal	NBR
Hose clamping segment material data	High alloy steel, non-corrosive