

Push-in T-fitting QSTL-10-32-UNF-1/4-U


Part number: 190821

FESTO

rotatable by 360°, male thread with external hexagon.

This product is only available if ordered from the Festo Corporation, USA.

Products to be discontinued. Available until 2011.

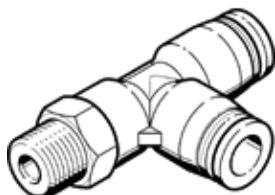

Data sheet

| Feature | Value |
|--|-----------------------------------|
| Size | Standard |
| Nominal size | 1.6 mm |
| Type of seal on screw-in stud | Sealing ring |
| Assembly position | Any |
| Container size | 1 |
| Design structure | Push/pull principle |
| Operating pressure | -0.95 ... 10 bar |
| Temperature dependent operating pressure | -0.95 ... 10 bar |
| Operating medium | Filtered compressed air Vacuum |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | -10 ... 60 °C |
| Authorisation | Germanischer Lloyd |
| Max. tightening torque | 1.5 Nm |
| Product weight | 15.5 g |
| Number of outputs | 2 |
| Number of supply lines | 1 |
| Pneumatic connection, supply line | Male thread UNF10-32 |
| Pneumatic connection, output | for tubing, 1/4" outside diameter |
| Colour of release ring | Grey |
| Materials note | Conforms to RoHS |
| Materials information, housing | PBT |
| Release ring material data | POM |
| Materials information for tubing seal | NBR |
| Hose clamping segment material data | High alloy steel, non-corrosive |