

# Ball valve QH-QS-1/8-1/8-NPT-U

Part number: 190886  
Product to be discontinued


with QS push-in connector.

This product is only available if ordered from the Festo Corporation, USA.

This type is suitable for vacuum.

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

FESTO

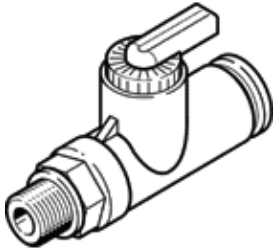

## Data sheet

Feature	Value
Type of actuation	manual
Mounting type	Threaded
Nominal size	2.5 mm
Operating pressure	-1 ... 10 bar
Ambient temperature	0 ... 60 °C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Sealing principle	soft
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Product weight	15.3 g
Materials note	Conforms to RoHS