

 

pressure regulator LRMA-QS-1/4-U

Part number: 190916
Product to be discontinued

FESTO

[With pressure gauge.](#)

[Type to be discontinued. Available until 2021. See Support Portal for alternative products.](#)

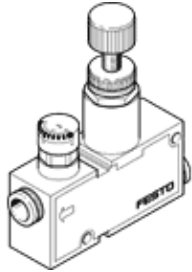

Data sheet

Feature	Value
Controller function	Output pressure constant
Pneumatic connection, port 1	QS-1/4
Pneumatic connection, port 2	QS-1/4
Mounting type	with through hole
Inlet pressure 1	0 ... 10 bar
Ambient temperature	0 ... 60 °C
Material housing	PBT-reinforced
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Assembly position	Any
Product weight	57 g
Material of threaded plug	Brass