


pressure regulator LR-10-32-UNF-QS-3/16-U

Part number: 190925
Product to be discontinued

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

FESTO

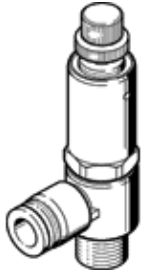

Data sheet

| Feature | Value |
|------------------------------|--|
| Controller function | Output pressure constant |
| Pneumatic connection, port 1 | 10-32 UNF-2A |
| Pneumatic connection, port 2 | QS-3/16 |
| Mounting type | Threaded |
| Inlet pressure 1 | 0 ... 10 bar |
| Ambient temperature | 0 ... 60 °C |
| Material housing | PBT-reinforced |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Assembly position | Any |
| Product weight | 17 g |
| Material of threaded plug | Brass |