


planar surface gantry EXCH-40-

Part number: 1923050

FESTO

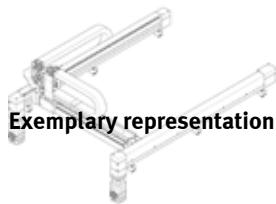

Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Size	40
Assembly position	Vertical Horizontal
Design structure	Planar surface gantry
Operating pressure	≤ 8 bar
Max. horizontal acceleration	50 m/s ²
Max. vertical acceleration	30 m/s ²
Max. horizontal speed	5 m/s
Max. vertical speed	4 m/s
Repetition accuracy	±0,1 mm
Duty cycle	100 %
CE mark (see declaration of conformity)	to EU directive for machinery
UKCA marking (see declaration of conformity)	To UK instructions for machines
PWIS conformity	VDMA24364 zone III
Storage temperature	-10 ... 60 °C
Relative air humidity	0 - 90 % non-condensing
Sound pressure level	74 dB(A)
Protection class	IP40
Ambient temperature	10 ... 50 °C
Rated load with maximum dynamic response	4 kg
Mounting type	With mounting kit With adjusting kit With slot nuts
Materials note	Conforms to RoHS