


# plug socket MSSD-F-S-M16

Part number: 192746

FESTO

with insulation-piercing contacts

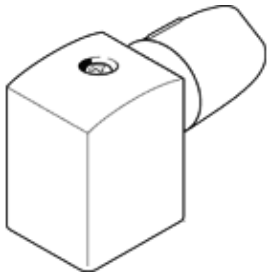

## Data sheet

Feature	Value
Connection frequency	10
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	35 g
Electrical connection	3-pin Plug socket Plug pattern type B to EN 175301-803
Cable diameter	5.5 ... 8 mm
Nominal conductor cross-section	0.5 ... 1 mm <sup>2</sup>
Protection class	IP67 to IEC 60529
Ambient temperature	-25 ... 90 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PA
Housing colour	Black