

Pressure regulator LRMA-1/16-NPT-QS-3/16-U

 

Part number: 192751

FESTO

With pressure gauge.

This product is only available if ordered from the Festo Corporation, USA.

Products to be discontinued. Available until 2011.

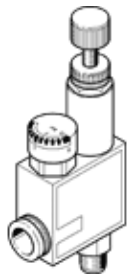

Data sheet

Feature	Value
Controller function	Output pressure constant
Pneumatic connection, port 1	NPT1/16-27
Mounting type	with through hole
Inlet pressure 1	0 ... 10 bar
Ambient temperature	0 ... 60 °C
Materials information, housing	PBT-reinforced
Operating medium	Filtered compressed air
Assembly position	Any
Product weight	51 g
Materials information for screw-in stud	Brass