


# stop element YSRWJ-8-14-A

Part number: 192966  
Product to be discontinued

FESTO

for linear module HMPL.

Type to be discontinued. Available until 2024. See Support Portal for alternative products.

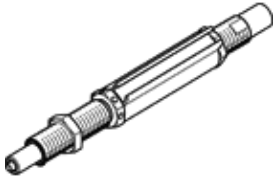

## Data sheet

Feature	Value
Size	8
Stroke	14 mm
Cushioning	self-adjusting Soft characteristic
Assembly position	Any
Precision adjustment	0.03 mm
Position detection	For proximity sensor
Max. impact speed	3 m/s
Reset time short	$\leq 0.2$ s
Reset time long	$< 1$ s
Mode of operation	single-acting pushing action
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	0 ... 60 °C
Cushioning length	14 mm
Max. stop force	500 N
Max. energy consumption per stroke	3 J
Max. energy consumption per hour	21,000 J
Max. residual energy	0.02 J
Reset force	3.5 N
Product weight	110 g
Mounting type	with lock nut
Material seals	NBR
Material housing	Brass Nickel plated
Material piston rod	High alloy steel