 



# Service unit FRCS-1/2-D-5M-O-DI-MAXI-A

Part number: 194993

FESTO

Filter/regulator/lubricator combination, S series, with lockable regulator head.

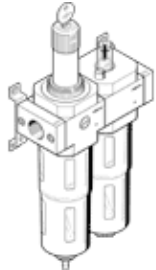

## Data sheet

Feature	Value
Size	Maxi
Series	D
Actuator lock	Rotary knob with integrated lock
Assembly position	Vertical +/- 5°
Grade of filtration	5 µm
Condensate drain	fully automatic
Design structure	Filter regulator without pressure gauge proportional standard mist lubricator
Max. condensate volume	43 cm <sup>3</sup>
Bowl guard	Metal bowl guard
Pressure gauge	G1/4" prepared
Pressure control range	0.5 ... 12 bar
Inlet pressure 1	1.5 ... 12 bar
Max. pressure hysteresis	0.4 bar
Standard nominal flow rate	3,000 l/min
Operating medium	Compressed air
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	2,880 g
Mounting type	Line installation
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/2
Materials information, housing	Zinc die-casting
Materials information for bowl	PC