 



Service unit combination LFRS-3/4-D-DI-MAXI-KB-A

Part number: 195193

FESTO

With lockable regulator head and pressure gauge, for nominal pressure 12 bar, for unlubricated compressed air.

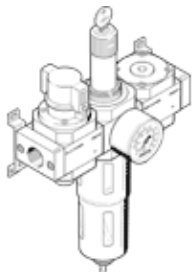

Data sheet

| Feature | Value |
|---|--|
| Size | Maxi |
| Series | D |
| Actuator lock | Rotary knob with integrated lock |
| Assembly position | Vertical +/- 5° |
| Grade of filtration | 40 µm |
| Condensate drain | fully automatic |
| Design structure | Branching module On/off valve Filter regulator with pressure gauge |
| Max. condensate volume | 43 cm ³ |
| Bowl guard | Metal bowl guard |
| Pressure gauge | with pressure gauge |
| Pressure control range | 0.5 ... 12 bar |
| Inlet pressure 1 | 2 ... 12 bar |
| Standard nominal flow rate | 7,000 l/min |
| Operating medium | Compressed air |
| Corrosion resistance classification CRC | 2 |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 3,740 g |
| Mounting type | Optional Line installation with accessories |
| Pneumatic connection, port 1 | G3/4 |
| Pneumatic connection, port 2 | G3/4 |
| Materials information, housing | Zinc die-casting |
| Materials information for bowl | PC |