 



# Pressure sensor SDE-2,5-10V/20MA

Part number: 19560

FESTO

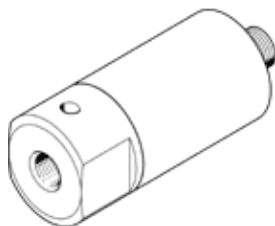

## Data sheet

Feature	Value
Short circuit strength	Yes
Measured variable	Relative pressure
Measurement method	Piezoresistive pressure sensor
Analogue output	0 - 10 V 0 - 20 mA
Operating voltage range DC	12 ... 30 V
Operating medium	Filtered compressed air, 40 µm filtration
CE Symbol	according to EU-EMV guideline
Protection class	IP65
Ambient temperature	0 ... 85 °C
Product weight	120 g
Pressure measuring range	0 ... 2.5 bar
Accuracy, FS	1 %
Electrical connection	Plug M12x1 4-pin
Mounting type	Threaded
Pneumatic connection	G1/4
Materials information, housing	Aluminium Anodised